

SYSTIMAX[®]
COMMSCOPE

CableGuide 360 ordering guide

Optimize every angle



YOUR NETWORK
YOUR FUTURE

CableGuide 360™ platform



Today's enterprise networks are edge-based and hyperconnected. Cabling in the backbone network and horizontal sub-systems is densifying—growing more complex and unmanageable. It's all converging on vertical and horizontal cabling managers that weren't designed to handle the strain.

Converging challenges

Today's cable management solutions lack the agility, ease of use and capacity that network managers need to adequately address the constant changes in their vertical and horizontal cabling. This isn't just our opinion. We asked our enterprise customers, and here's what they said they needed from their cable management solution:

- **Simplified and user-friendly:** Easier and faster to deploy, configure, move and manage
- **Increased capacity:** Enable more cabling, cleaner organization and better fiber protection
- **Flexible and future-ready:** Various cabinet and panel sizes, configurations and cable types
- **Globally available:** All SKUs available in all markets, when and where you need them

SYSTIMAX CableGuide 360

The CableGuide 360 portfolio is uniquely designed to address the evolving challenges of today's fiber-dense and fluid cabling infrastructure.



Intuitive design: The CableGuide 360 platform features a streamlined design and simplified operation. Flexible, single-handed door operation, strong but flexible fingers and cable exits that are precisely aligned with rack-mount components help simplify cable management, maintain optimal bend radius and protect your network's ROI.



Highly adaptable: Modular and customizable, the CableGuide 360 portfolio provides a wide range of cabinet and panel sizes, configurations and mounting options. The result is a flexible, future-ready solution that easily adapts to support virtually any application and environment.



Global availability: With CommScope's global production and redundant regional distribution network, all CableGuide 360 solutions are available when and where you need them.

Performance backed up Warranties


At the same time, the CableGuide 360 platform is the only cable management solution that's fully backed by the SYSTIMAX Assurance™ program and the SYSTIMAX 25-Year Warranty. Our Application Assurance Program provides confidence in writing.

SYSTIMAX® CableGuide 360™

The SYSTIMAX CableGuide 360 portfolio is uniquely designed to address the evolving challenges of today's fiber-dense and fluid cabling infrastructures.

Intuitive design: The CableGuide 360 platform features a streamlined design and simplified operation with flexible, single-handed door operation and strong but flexible fingers. Cable exits are precisely aligned with rack-mount components to help simplify cable management, maintain optimal bend radius and protect your network's ROI.

Highly adaptable: Modular and customizable, the CableGuide 360 portfolio provides a wide range of cabinet and panel sizes, configurations and mounting options. The result is a flexible, future-ready solution that supports a variety of cabling and connector types and easily adapts to virtually any application and environment.

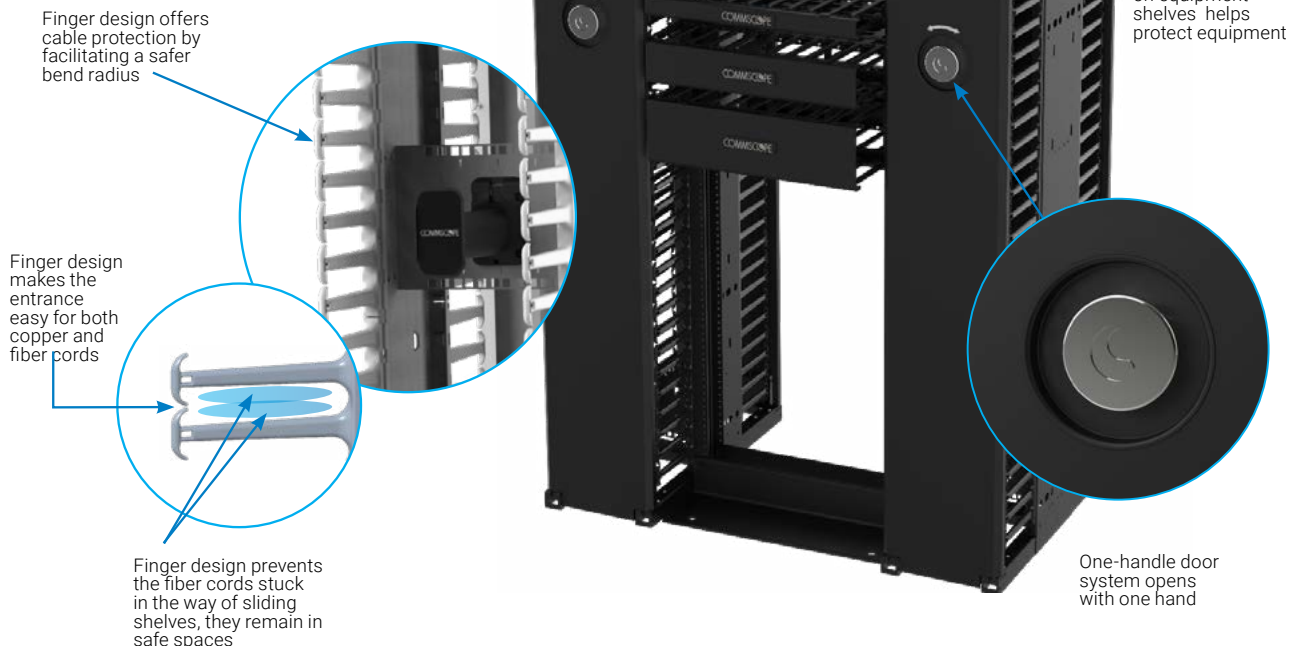

Global availability: With CommScope's global production and redundant regional distribution network, all CableGuide 360 solutions are available when and where you need them.

Application assurance in writing: The CableGuide 360 platform is the only cable management solution that's fully backed by the SYSTIMAX Assurance™ program and the SYSTIMAX 25-Year Warranty. Our Application Assurance Program provides confidence in writing.

The difference is in the details

The CableGuide 360 platform features vertical cable managers (VCMs) and horizontal cable managers (HCMs) that are uniquely designed for ease of use, agile growth and superior cable protection.

Simplified and user-friendly VCMs

- Patented, one-handed door design
- Patented visual door closed/ajar indicator
- Easy-to-open trough cover
- Quick-release spool can be repositioned
- Fingers align with rack-mount units
- Accepts 19-inch vertical and M2400 horizontal panels
- Strong, lightweight and pre-assembled

Flexible and future-ready

- Zero U capacity VCMs maximize space usage
- 1U, 2U, 3U HCM sizes
- VCMs offer 6-in, 8-in, 10-in and 12-in widths
- VCMs available in 84-in and 96-in heights
- Black, silver and white color options
- Diverse cable types/dimensions, high-fiber-count assemblies, copper and fiber cabling
- Compatible with most two- or four-post racks

Cable protection and application support


- Strong, pliable fingers support more cables
- Designed to maintain optimal bend radius
- Smart routing reduces pinching and crushing
- VCM spools, accessories for cabling storage
- Stable, durable build, lighter trough covers
- End-to-end solution that's globally available
- Covered by the SYSTIMAX Assurance and 25-Year Warranty

CableGuide 360 or CableGuide Essential™

The CableGuide 360 solution is a full-featured system designed to address the challenges of a complex cabling environment. For customers who don't need the full functionality, we offer the CableGuide Essential solution, with all the innovation and value in a more streamlined, basic design.

Organize. Manage. Protect. Repeat.

With simplified, user-friendly designs, incredible flexibility and cable protection, and application support, one innovative portfolio can organize, manage and protect your vertical and horizontal patching applications. Now and in the future. For more information about the CableGuide 360 and CableGuide Essential cable management solutions, [visit the solution page](#).

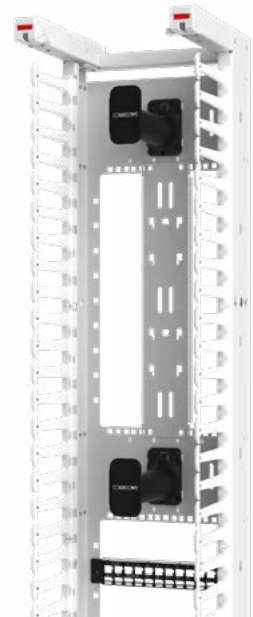

Back frame with quick release removable spools



Rack mount units



Flat or angled panels can be used

CableGuide 360 Vertical Cable Managers (VCMs)

Material ID	Product number	Description
760236905	VCM2-SS-84-6BK	Vertical Cable Management Kit, 6 in X 84 in (152 mm X 2134 mm) Single Sided, With Door, Black
760236906	VCM2-SS-84-8BK	Vertical Cable Management Kit, 8 in X 84 in (203 mm X 2134 mm) Single Sided, With Door, Black
760236907	VCM2-SS-84-10BK	Vertical Cable Management Kit, 10 in X 84 in (254 mm X 2134 mm) Single Sided, With Door, Black
760236908	VCM2-SS-84-12BK	Vertical Cable Management Kit, 12 in X 84 in (305 mm X 2134 mm) Single Sided, With Door, Black
760236901	VCM2-DS-84-6BK	Vertical Cable Management Kit, 6 in X 84 in (152 mm X 2134 mm) Double Sided, With Doors, Black
760236902	VCM2-DS-84-8BK	Vertical Cable Management Kit, 8 in X 84 in (203 mm X 2134 mm) Double Sided, With Doors, Black
760236903	VCM2-DS-84-10BK	Vertical Cable Management Kit, 10 in X 84 in (254 mm X 2134 mm) Double Sided, With Doors, Black
760236904	VCM2-DS-84-12BK	Vertical Cable Management Kit, 12 in X 84 in (305 mm X 2134 mm) Double Sided, With Doors, Black
760260432	VCM2-SS-96-6BK	Vertical Cable Management Kit, 6 in X 96 in (152 mm X 2438 mm) Single Sided, With Door, Black
760260433	VCM2-SS-96-8BK	Vertical Cable Management Kit, 8 in X 96 in (203 mm X 2438 mm) Single Sided, With Door, Black
760260434	VCM2-SS-96-10BK	Vertical Cable Management Kit, 10 in X 96 in (254 mm X 2438 mm) Single Sided, With Door, Black
760260435	VCM2-SS-96-12BK	Vertical Cable Management Kit, 12 in X 96 in (305 mm X 2438 mm) Single Sided, With Door, Black
760260444	VCM2-DS-96-6BK	Vertical Cable Management Kit, 6 in X 96 in (152 mm X 2438 mm) Double Sided, With Doors, Black
760260447	VCM2-DS-96-8BK	Vertical Cable Management Kit, 8 in X 96 in (203 mm X 2438 mm) Double Sided, With Doors, Black
760260450	VCM2-DS-96-10BK	Vertical Cable Management Kit, 10 in X 96 in (254 mm X 2438 mm) Double Sided, With Doors, Black
760260453	VCM2-DS-96-12BK	Vertical Cable Management Kit, 12 in X 96 in (305 mm X 2438 mm) Double Sided, With Doors, Black
760260362	VCM2-SS-84-6SL	Vertical Cable Management Kit, 6 in X 84 in (152 mm X 2134 mm) Single Sided, With Door, Silver
760260363	VCM2-SS-84-8SL	Vertical Cable Management Kit, 8 in X 84 in (203 mm X 2134 mm) Single Sided, With Door, Silver
760260364	VCM2-SS-84-10SL	Vertical Cable Management Kit, 10 in X 84 in (254 mm X 2134 mm) Single Sided, With Door, Silver
760260365	VCM2-SS-84-12SL	Vertical Cable Management Kit, 12 in X 84 in (305 mm X 2134 mm) Single Sided, With Door, Silver
760260354	VCM2-DS-84-6SL	Vertical Cable Management Kit, 6 in X 84 in (152 mm X 2134 mm) Double Sided, With Doors, Silver
760260356	VCM2-DS-84-8SL	Vertical Cable Management Kit, 8 in X 84 in (203 mm X 2134 mm) Double Sided, With Doors, Silver
760260358	VCM2-DS-84-10SL	Vertical Cable Management Kit, 10 in X 84 in (254 mm X 2134 mm) Double Sided, With Doors, Silver
760260360	VCM2-DS-84-12SL	Vertical Cable Management Kit, 12 in X 84 in (305 mm X 2134 mm) Double Sided, With Doors, Silver
760260436	VCM2-SS-96-6SL	Vertical Cable Management Kit, 6 in X 96 in (152 mm X 2438 mm) Single Sided, With Door, Silver
760260437	VCM2-SS-96-8SL	Vertical Cable Management Kit, 8 in X 96 in (203 mm X 2438 mm) Single Sided, With Door, Silver
760260438	VCM2-SS-96-10SL	Vertical Cable Management Kit, 10 in X 96 in (254 mm X 2438 mm) Single Sided, With Door, Silver
760260439	VCM2-SS-96-12SL	Vertical Cable Management Kit, 12 in X 96 in (305 mm X 2438 mm) Single Sided, With Door, Silver



CableGuide 360 Vertical Cable Managers (VCMs)

Material ID	Product number	Description
760260445	VCM2-DS-96-6SL	Vertical Cable Management Kit, 6 in X 96 in (152 mm X 2438 mm) Double Sided, With Doors, Silver
760260448	VCM2-DS-96-8SL	Vertical Cable Management Kit, 8 in X 96 in (203 mm X 2438 mm) Double Sided, With Doors, Silver
760260451	VCM2-DS-96-10SL	Vertical Cable Management Kit, 10 in X 96 in (254 mm X 2438 mm) Double Sided, With Doors, Silver
760260454	VCM2-DS-96-12SL	Vertical Cable Management Kit, 12 in X 96 in (305 mm X 2438 mm) Double Sided, With Doors, Silver
760260366	VCM2-SS-84-6WH	Vertical Cable Management Kit, 6 in X 84 in (152 mm X 2134 mm) Single Sided, With Door, White
760260367	VCM2-SS-84-8WH	Vertical Cable Management Kit, 8 in X 84 in (203 mm X 2134 mm) Single Sided, With Door, White
760260368	VCM2-SS-84-10WH	Vertical Cable Management Kit, 10 in X 84 in (254 mm X 2134 mm) Single Sided, With Door, White
760260369	VCM2-SS-84-12WH	Vertical Cable Management Kit, 12 in X 84 in (305 mm X 2134 mm) Single Sided, With Door, White
760260355	VCM2-DS-84-6WH	Vertical Cable Management Kit, 6 in X 84 in (152 mm X 2134 mm) Double Sided, With Doors, White
760260357	VCM2-DS-84-8WH	Vertical Cable Management Kit, 8 in X 84 in (203 mm X 2134 mm) Double Sided, With Doors, White
760260359	VCM2-DS-84-10WH	Vertical Cable Management Kit, 10 in X 84 in (254 mm X 2134 mm) Double Sided, With Doors, White
760260361	VCM2-DS-84-12WH	Vertical Cable Management Kit, 12 in X 84 in (305 mm X 2134 mm) Double Sided, With Doors, White
760260440	VCM2-SS-96-6WH	Vertical Cable Management Kit, 6 in X 96 in (152 mm X 2438 mm) Single Sided, With Door, White
760260441	VCM2-SS-96-8WH	Vertical Cable Management Kit, 8 in X 96 in (203 mm X 2438 mm) Single Sided, With Door, White
760260442	VCM2-SS-96-10WH	Vertical Cable Management Kit, 10 in X 96 in (254 mm X 2438 mm) Single Sided, With Door, White
760260443	VCM2-SS-96-12WH	Vertical Cable Management Kit, 12 in X 96 in (305 mm X 2438 mm) Single Sided, With Door, White
760260446	VCM2-DS-96-6WH	Vertical Cable Management Kit, 6 in X 96 in (152 mm X 2438 mm) Double Sided, With Doors, White
760260449	VCM2-DS-96-8WH	Vertical Cable Management Kit, 8 in X 96 in (203 mm X 2438 mm) Double Sided, With Doors, White
760260452	VCM2-DS-96-10WH	Vertical Cable Management Kit, 10 in X 96 in (254 mm X 2438 mm) Double Sided, With Doors, White
760260455	VCM2-DS-96-12WH	Vertical Cable Management Kit, 12 in X 96 in (305 mm X 2438 mm) Double Sided, With Doors, White



CableGuide 360 Horizontal Cable Managers (HCMs)

Material ID	Product number	Description
760259431	HTK2-19-SS-1U-BK	Horizontal Trough Kit, 1 RU, 19 in, Single Sided, Black
760259432	HTK2-19-SS-2U-BK	Horizontal Trough Kit, 2 RU, 19 in, Single Sided, Black
760259433	HTK2-19-SS-3U-BK	Horizontal Trough Kit, 3 RU, 19 in, Single Sided, Black
760259434	HTK2-19-DS-1U-BK	Horizontal Trough Kit, 1 RU, 19 in, Double Sided, Black
760259435	HTK2-19-DS-2U-BK	Horizontal Trough Kit, 2 RU, 19 in, Double Sided, Black
760259436	HTK2-19-DS-3U-BK	Horizontal Trough Kit, 3 RU, 19 in, Double Sided, Black
760260411	HTK2-19-SS-1U-SL	Horizontal Trough Kit, 1 RU, 19 in, Single Sided, Silver
760260412	HTK2-19-SS-2U-SL	Horizontal Trough Kit, 2 RU, 19 in, Single Sided, Silver
760260413	HTK2-19-SS-3U-SL	Horizontal Trough Kit, 3 RU, 19 in, Single Sided, Silver
760260414	HTK2-19-DS-1U-SL	Horizontal Trough Kit, 1 RU, 19 in, Double Sided, Silver
760260415	HTK2-19-DS-2U-SL	Horizontal Trough Kit, 2 RU, 19 in, Double Sided, Silver
760260370	HTK2-19-DS-3U-SL	Horizontal Trough Kit, 3 RU, 19 in, Double Sided, Silver
760260371	HTK2-19-SS-1U-WH	Horizontal Trough Kit, 1 RU, 19 in, Single Sided, White
760260372	HTK2-19-SS-2U-WH	Horizontal Trough Kit, 2 RU, 19 in, Single Sided, White
760260373	HTK2-19-SS-3U-WH	Horizontal Trough Kit, 3 RU, 19 in, Single Sided, White
760260429	HTK2-19-DS-1U-WH	Horizontal Trough Kit, 1 RU, 19 in, Double Sided, White
760260430	HTK2-19-DS-2U-WH	Horizontal Trough Kit, 2 RU, 19 in, Double Sided, White
760260431	HTK2-19-DS-3U-WH	Horizontal Trough Kit, 3 RU, 19 in, Double Sided, White



HTK2-19-DS-1U-BK




HTK2-19-DS-3U-BK

CableGuide Essential Vertical Cable Managers (VCMs)

Material ID	Product number	Description
760260759	VCM-SS-84-6BK-TD	Vertical Cable Management Kit, 6 in X 84 in (152 mm X 2134 mm) Single Sided, With Twin Covers, Black
760260760	VCM-SS-84-8BK-TD	Vertical Cable Management Kit, 8 in X 84 in (203 mm X 2134 mm) Single Sided, With Twin Covers, Black
760260761	VCM-DS-84-6BK-TD	Vertical Cable Management Kit, 6 in X 84 in (152 mm X 2134 mm) Double Sided, With Twin Covers, Black
760260762	VCM-DS-84-8BK-TD	Vertical Cable Management Kit, 8 in X 84 in (203 mm X 2134 mm) Double Sided, With Twin Covers, Black
760260763	VCM-SS-84-6WH-TD	Vertical Cable Management Kit, 6 in X 84 in (152 mm X 2134 mm) Single Sided, With Twin Covers, White
760260764	VCM-SS-84-8WH-TD	Vertical Cable Management Kit, 8 in X 84 in (203 mm X 2134 mm) Single Sided, With Twin Covers, White
760260765	VCM-DS-84-6WH-TD	Vertical Cable Management Kit, 6 in X 84 in (152 mm X 2134 mm) Double Sided, With Twin Covers, White
760260766	VCM-DS-84-8WH-TD	Vertical Cable Management Kit, 8 in X 84 in (203 mm X 2134 mm) Double Sided, With Twin Covers, White



 VCM-SS-84-6BK-TD



VCM-DS-84-6BK-TD



VCM-SS-84-6WH-TD



VCM-DS-84-8WH-TD

CableGuide Essential Horizontal Cable Managers (HCMs)

Material ID	Product number	Description
760259386	HCM2-19-SS-1U-BK	Horizontal Cable Management Kit, 1 RU, 19 in, Single Sided, Black
760259387	HCM2-19-SS-2U-BK	Horizontal Cable Management Kit, 2 RU, 19 in, Single Sided, Black
760259816	HCM2-19-SS-1U-WH	Horizontal Cable Management Kit, 1 RU, 19 in, Single Sided, White
760259817	HCM2-19-SS-2U-WH	Horizontal Cable Management Kit, 2 RU, 19 in, Single Sided, White



HCM2-19-SS-1U-BK



HCM2-19-SS-1U-WH



HCM2-19-SS-2U-BK



HCM2-19-SS-2U-WH

CommScope pushes the boundaries of communications technology with game-changing ideas and ground-breaking discoveries that spark profound human achievement.

We collaborate with our customers and partners to design, create and build the world's most advanced networks. It is our passion and commitment to identify the next opportunity and realize a better tomorrow.

For more information, visit the SYSTIMAX 2.0 solutions page

www.systimax.com



SYSTIMAX®
COMMScope

systimax.com

Visit our website or contact your local CommScope representative for more information.

© 2025 CommScope, LLC. All rights reserved. CommScope and the CommScope logo are registered trademarks of CommScope and/or its affiliates in the U.S. and other countries. For additional trademark information see <https://www.commscope.com/trademarks>. All product names, trademarks and registered trademarks are property of their respective owners.

CO-120220-EN (08/25)