



RUCKUS® ACCESSORY GUIDE

[INDOOR AP ACCESSORIES](#)

[OUTDOOR AP ACCESSORIES](#)






[ELECTRICAL](#)

[FIBER ACCESSORIES](#)

RUCKUS ACCESSORY GUIDE

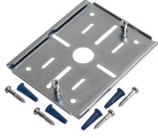INDOOR AP ACCESSORIES



INDOOR	SKU	Compatible Products	Description	Kit Contents
	902-0120-0000	<div> R310 R320 R350 R350e R370 R510 R550 R560 </div> <div> R610 R650 R670 R710 R720 R730 R750 R760 </div> <div> R770 R850 </div> <div>Fits AP, but does not support padlock security</div>	Multipurpose mounting bracket for R-Series indoor AP's. Supports mounting to hard wall, ceiling, pole or truss. (Secure Mounting Bracket for WiFi-5 and WiFi-6 R-series APs without padlock support)	(1) Sheet metal mounting bracket (2) #6 wood screws & anchors
	902-0136-0000	H350 H550	Optional bracket, used to mount wall switch AP to locations where there is no junction box available for mounting	(1) Plastic bracket (2) Torx screws
	902-0123-0000	<div> R310 R500 R510 R550 R560 R610 </div> <div> R650 R710 R720 R730 R750 R770 R850 </div>	Flush-frame acoustic ceiling bracket for R-Series AP. Flush-frame only—not applicable for standard (recessed-frame) acoustic ceiling.	(1) Mounting bracket (2) Mounting guide
	902-0195-0000	<div> M510 R310 R320 R350 R350e R510 R550 R600 </div> <div> R610 R650 R710 R720 R730 R750 R850 </div>	Spare, T-bar ceiling mount kit for mounting to flush frame ceiling	(1) Plastic T-bar bracket (1) Plastic locking tab
	902-0196-0000	R370 R560 R670 R770	Spare, T-bar ceiling mount kit for mounting R560 and R770 to flush frame ceiling	(1) Plastic T-bar bracket (1) Plastic locking tab
	902-0700-0000	R350 R370 R550 R650 R670 R750 R560	Under-the-seat Stadium Enclosure for RUCKUS indoor Wi-Fi 6/6E APs. 35-degree and 45-degree mounting brackets are included.	(1) Stadium enclosure assembly (2) Thermal Interface Material (TIM) (2) Mounting brackets (4) M8 flange screws
	902-0701-0000	Stadium Enclosure	0-degree flush mounting bracket kit. Horizontal mounting for Stadium Enclosure (902-0700-0000)	(2) Mounting brackets (4) M8 flange screws

RUCKUS ACCESSORY GUIDE

OUTDOOR AP ACCESSORIES



OUTDOOR






	SKU	Compatible Products	Description	Kit Contents
	902-0125-0000	T310 T310c T310d T310s T310n T350c T350d T350se T610 T610s T670 T710 T710s T750	Mounting Kit for Outdoor T-series AP as the compatibility list will display which ones are applicable. (T610, T710, T310, T350, T750)	(1) Mounting Bracket Hardware Kit (1) U Joint Bracket (1) Wall Mount Bracket (1) AP bracket (2) Linkage Brackets (1) Safety Cable Kit (1) Quick Setup Guide
	902-0134-0000	Q910 T310n T310s T350 T610 T610s T670 T670sn T710 T710s T750	Outdoor AP mounting bracket (weatherized aluminum), 180-degree adjustment range in both azimuth and elevation. Mounting support for solid wall or ceiling, vertical or horizontal pole 1" to 4" in diameter using enclosed mounting hardware. Pole diameter greater than 4" can be supported with user-supplied clamps.	(1) Mounting bracket: weatherized aluminum (1) Hanger mount: weatherized aluminum (1) Extension: weatherized aluminum (2) M8 hex bolts with spring locks & washers (4) SAE32 steel clamps, 2.5" (4) M4 x 12mm machine screws with spring locks & washers (4) 0.25-28 x 0.625" machine screws with spring locks & washers
	902-0703-0000	T750	The T750 strand mount bracket mounts the access point (AP) to an overhead strand and shields the AP from light falling debris and hail.	(1) strand bracket (2) strand bracket kit (4) 0.250-20 x .75-inch carriage bolts (4) 0.250-20, hex nuts (4) M4 x 8-mm screws with washers (10) 0.250 flat washers (10) 0.250 split lock washers (6) 0.250-28 x .50-inch hex bolts RUCKUS QR code insert
	902-0707-0000	T670 omni	Under-Seat Flush Mounting Bracket	(1) under-seat mounting enclosure with conduit port plugs (1) metal internal bracket (6) M6 x 12mm screws with lock and flat washer (2) M6 x 50mm sleeve anchors Plastic cable cover with captive screws QR code insert card

RUCKUS ACCESSORY GUIDE

ELECTRICAL






ELECTRICAL

	SKU	Compatible Products	Description	Kit Contents
	902-0162-XX00	E510 H320 H350 H510 M510 P300 R310	R320 R350 R510 R550 R610 R710	Regional PoE Adapter (10/100/1000Mbps) (Qty: 1) PoE module (10/100/1000 Mbps) LAN port: RJ-45 jack PoE port: RJ-45 jack, 24 Watts PoE AC input: 100-240 VAC ~ 50/60 Hz (Qty: 1) AC cable (length 2ft / 0.6m)
	902-0180-XXYY	H550 R560 R650 R720 R730 R750	R760 R850	(1) Country-specific power cord, IEC, 6ft (1) PoE module (10/100/1000Mbps) Input: 100-240VAC ~ 50/60Hz 1.0A Output: 48VDC 1250mA (60W) Data port: RJ-45 jack PoE/data port: RJ-45 jack Dimensions 123 x 61 x 40 mm
	902-1180-XX00	R370 R560 R650 R670 R730 R750 R770 R850		(1) Country-specific cord, IEC, 6ft (1) PoE module (10/ 100/ 1000/ 2500/ 5000/ 10000Mbps) Input: 100-24VAC - 50/60Hz 1.2A Output: 54VDC 1.12A (60W) Data port: RJ-45 jack PoE/data port: RJ-45 jack Dimensions: 123 x 61 x 40 mm
	902-1169-XX00	E510 M510 R310 R550 R610 R710		(1) Country-specific power cord, IEC, 6ft (1) Power adapter Input: 100-240VAC ~ 50/60Hz 0.6A Output: 12VDC 2.0A AC plug: country-specific DC plug: Right-angle, 2.5 x 5.5 x 10 mm (ID x OD x L) female, positive center DC cable length 1.5m
	902-1170-XX00	R370 R560 R650 R670 R720 R730 R750 R770 R850	KIT, SPARE, Modular AC/DC Power Adapter, 48V - 36W, w/ XX Power Cord, 1 Unit	(1) Power Supply, DC Switching Mode, 48VDC 0.75A 36W, Inlet-C14, RoHS (1) Power Cord, XX, RoHS, IEC 320, 6Ft Long

RUCKUS ACCESSORY GUIDE

ELECTRICAL



ELECTRICAL	SKU	Compatible Products	Description	Kit Contents
	902-0170-XX00	H350 H510 Fiber Backpack	Regional 48W Power Adapter	(1) Country-specific power cord, IEC, 6ft (1) Power adapter Input: 100-240VAC ~ 50/60Hz 0.8A Output: 48VDC 0.68A DC plug: 0.7 x 2.35 x 13 mm (ID x OD x L) female, positive center DC cable length 1.5m
	902-2170-XXYY	H510 H550 H350 H550 Fiber Backpack	Regional 50W power adapter (Sold in quantities of 1, 10)	(1) Country-specific power cord, IEC, 6ft (1) Power adapter Input: 100-240VAC ~ 50/60Hz 0.8A Output: 48VDC 1A
	902-2171-XX00	R650 R720 R730 R750 R760 R850	Regional 48W Power Adapter	(1) Country-specific power cord, IEC, 6ft (1) Power adapter Input: 115-230VAC 50/60Hz 0.8A Output: 48VDC, 1A DC plug: 1.35mmx 3.5mmx13mm (IDxODxL) female, positive center DC cable length 1.5m (right angle DC connector)

When ordering PoE injectors or power supplies, you must specify the destination region by indicating -US, -EU, -AU, -BR, -CN, -IN, -JP, -KR, -SA, -UK, or -UN instead of -XX. And 00 instead of YY for quantity 1, and 10 instead of YY for quantity 10

RUCKUS ACCESSORY GUIDE

ELECTRICAL



ELECTRICAL

ELECTRICAL

	SKU	Compatible Products		Description	Kit Contents
	902-0173-XX00	R310 R320 R350 R500 R510		Regional Power Adapters	(1) Country-specific power adapter — right angle plug Input: 100-240VAC ~ 50/60Hz 0.4A Output: 12VDC 1.0A AC plug: country-specific DC plug: Right-angle, 2.1 x 5.5 x 9.5 mm (ID x OD x L) female, positive center DC cable length 1.8m
	902-0183-0000	T310 T350c T350d T350se T610 T610s T670 T670sn		Spare cable gland for weatherizing the RJ-45 ports on outdoor APs.	(1) weatherizing cable gland
	902-1121-0000	T310c T310d T310n T310s T350c T350d T350se	T670 T670sn T710 T710s T750 T750se T811	Spare cable gland for weatherizing the RJ-45 port or the DC input on outdoor APs (contains inserts for 1 or 2 holes).	(1) weatherizing cable gland
	902-0185-0000	T710 T710s T750 P01-0300-0000 (Fiber Node)		Spare Weatherized AC Connector; contains 4-pin AC connector.	(1) 4-pin female cable connector strain relief with clamping ring compatible with cable diameter 6-12.5mm

When ordering PoE injectors or power supplies, you must specify the destination region by indicating -US, -EU, -AU, -BR, -CN, -IN, -JP, -KR, -SA, -UK, or -UN instead of -XX. And 00 instead of YY for quantity 1, and 10 instead of YY for quantity 10

RUCKUS ACCESSORY GUIDE

ELECTRICAL



ELECTRICAL




	SKU	Compatible Products	Description	Kit Contents
	902-0174-XX00	SmartZone 144 SmartZone 144-D	Regional IEC Power Chord for SmartZone 144 and 144-D Qty 1, MOQ 10.	(1) Country-specific power cord, IEC, 6ft
	902-S310-AC00	SmartZone 300	KIT, SPARE, AC Power Supply, SZ-300 (use with 902-1174-xx00 power cord)	(1) Power Supply, AC PSU Module, 1400W (1) Manual, Quick Setup Guide, AC Power Supply, SZ 300 (1) Label, POD, Packaging Box/Bag (1.25 in x 2.25 in) (1) PKG, BOX, Power Supply, 1 Unit (385 x 151 x 118mm) (1) PKG, Foam Insert, Front (145 x 105 x 110mm) (1) PKG, Foam Insert, Rear (145 x 90 x 110mm)
	902-S301-DC00	SmartZone 300	KIT, SPARE, DC Power Supply, SZ-300	(1) Power Supply, DC PSU Module, 1200W (1) Manual, Quick Setup Guide, DC Power Supply, SZ 300 (1) Label, POD, Packaging Box/Bag (1.25 in x 2.25 in) (1) PKG, BOX, Power Supply, 1 Unit (385 x 151 x 118mm) (1) PKG, Foam Insert, Front (145 x 105 x 110mm) (1) PKG, Foam Insert, Rear (145 x 90 x 110mm)
	902-S302-DC00	SmartZone 300	KIT, SPARE, DC Power Cable, SZ-300	(1) Cable, DC Power Supply (1) Manual, Quick Setup Guide, DC Power Cord Accessory (1) Label, POD, Packaging Box/Bag (1.25 in x 2.25 in) (1) PKG, BAG, TBD x TBDmm, 0.05mm THK LDPE, Clear (1) PKG, BOX, Spares, (OD TBD x TBD x TBD mm)
	902-S320-0000	SmartZone 300	KIT, SPARE, FAN ASSY, SZ-300	(1) Manual, Quick Setup Guide, Fan Assembly, (SZ 300) (1) Label, POD, Packaging Box/Bag (1.25 in x 2.25 in) (1) PKG, BOX, Fan Assembly (146 x 96 x 144mm)
	902-S330-0000	SmartZone 300	KIT, SPARES, Slide Rail Rack Mount Kit, SZ-300	(1) KIT, Slide Rail (1) Quick Setup Guide, SmartZone 300 Rack Mount Kit

When ordering PoE injectors or power supplies, you must specify the destination region by indicating -US, -EU, -AU, -BR, -CN, -IN, -JP, -KR, -SA, -UK, or -UN instead of -XX. And 00 instead of YY for quantity 1, and 10 instead of YY for quantity 10

RUCKUS ACCESSORY GUIDE

ELECTRICAL



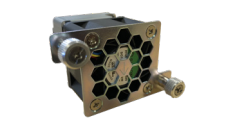

















ELECTRICAL	SKU	Compatible Products	Description	Kit Contents
	902-S340-0000	SmartZone 300	KIT, SPARE, Console Cable, (RJ45 to USB)	(1) CABLE, Console, USB RS232-RJ45, 6FT Lg (1) Manual, Quick Setup Guide, Console Cable (SZ 300) (1) Label, POD, Packaging Box/Bag (1.25 in x 2.25 in) (1) PKG, BAG, 170 x 240mm, 0.04mm THK, LDPE, Clear
	902-S110-0000	SmartZone 144 SmartZone 144-D	KIT, SPARE, AC Power Supply, SZ144/144-D	(1) Power Supply, AC PSU Module, 300W (1) Manual, Quick Setup Guide, AC Power Supply, SZ 144 (1) Label, POD, Packaging Box/Bag (1.25 in x 2.25 in) (1) PKG, BOX, Power Supply, 1 Unit (100 x 350 x 45 mm) (1) PKG, Foam Insert, EPE
	902-S120-0000	SmartZone 144 SmartZone 144-D	KIT, SPARE, FAN ASSY, SZ144/SZ144-D	(1) FAN, 12VDC 24.9CFM (40 x 40 x 28mm) (1) Manual, Quick Setup Guide, Fan Assembly, (SZ 144) (1) Label, POD, Packaging Box/Bag (1.25 in x 2.25 in) (1) PKG, BOX, Fan Assembly (130 x 113 x 48mm)

RUCKUS ACCESSORY GUIDE

ELECTRICAL



POWER CORDS











Outlet Connector	Equipment Connector	SKU	Compatible Products	Description	Kit Contents
		PC AUS	All ICX Switches (except ICX8200-C08ZP and ICX7150-C08PT)	Power Outlet Connector: AS 3112 Equipment Connector: C13 Length: 2.5m Rating: 250v/10A	Power Cord, Australia, 250V 10A
		PC-C13C14	All ICX Switches (except ICX8200-C08ZP and ICX7150-C08PT)	Power Outlet Connector: C14 Equipment Connector: C13 Length: 2.0m Rating: 250v/10A	C13/C14 150 Power Cord
		PCCHINA-IEC309	All ICX Switches (except ICX8200-C08ZP and ICX7150-C08PT)	Power Outlet Connector: IEC 60309 Equipment Connector: C13 Length: 2.5m Rating: 110v/10A	Power Cord, IEC309 TO C13, China, 110V 10A
		PCCHINA2-IEC309	All ICX Switches (except ICX8200-C08ZP and ICX7150-C08PT)	Power Outlet Connector: IEC 60309 Equipment Connector: C13 Length: 2.5m Rating: 250v/10A	Power Cord, IEC309 TO C13, China, 250V 10A
		PCEURO	All ICX Switches (except ICX8200-C08ZP and ICX7150-C08PT)	Power Outlet Connector: CEE 7/7 Equipment Connector: C13 Length: 2.5m Rating: 250v/10A	Power Cord for VIIG to C13, Europe, 250V 10A
		PCINDIA	All ICX Switches (except ICX8200-C08ZP and ICX7150-C08PT)	Power Outlet Connector: BS 546 Equipment Connector: C13 Length: 2.5m Rating: 250v/10A	Power Cord, India, 250V 10A
		PCITALY-CEI	All ICX Switches (except ICX8200-C08ZP and ICX7150-C08PT)	Power Outlet Connector: CEI 23-16 Equipment Connector: C13 Length: 2.5m Rating: 250v/10A	PWRCD, ITALY,10A,250V,2.5M, CEI 23-16/C13
		PCJAPAN	All ICX Switches (except ICX8200-C08ZP and ICX7150-C08PT)	Power Outlet Connector: JIS 8303 Equipment Connector: C13 Length: 2.0m Rating: 125v/13A	Power Cord, Japan, 125V 13A
		PCSWISS-C1312G-HF	All ICX Switches (except ICX8200-C08ZP and ICX7150-C08PT)	Power Outlet Connector: SEV 1011 Equipment Connector: C13 Length: 2.5m Rating: 250v/10A	Power Cord for SEV1011 TO C13, Switzerland, 250V 10A

RUCKUS ACCESSORY GUIDE

ELECTRICAL



POWER CORDS

Outlet Connector	Equipment Connector	SKU	Compatible Products	Description	Kit Contents
		PCUK	All ICX Switches (except ICX8200-C08ZP and ICX7150-C08PT)	Power Outlet Connector: BS 1363 Equipment Connector: C13 Length: 2.5m Rating: 250v/10A	Power Cord, United Kingdom, 250V 10A. 2.5m
		PCUSA	All ICX Switches (except ICX8200-C08ZP and ICX7150-C08PT)	Power Outlet Connector: NEMA 5-15 Equipment Connector: C13 Length: 2.0m Rating: 125v/10A	Power Cord, USA, NEMA5-15/C13, 10A, 125V, 2m
		PCUSA2	All ICX Switches (except ICX8200-C08ZP and ICX7150-C08PT)	Power Outlet Connector: NEMA 5-15 Equipment Connector: C13 Length: 2.0m Rating: 125v/13A	Power Cord, USA, NEMA5-15/C13, 13A, 125V, 2m
		PCUSA-3M	All ICX Switches (except ICX8200-C08ZP and ICX7150-C08PT)	Power Outlet Connector: NEMA 5-15 Equipment Connector: C13 Length: 3.0m Rating: 125v/10A	Power Cord, USA, NEMA5-15/C13, 10A, 125V, 3m
		902-0174-BR00	All ICX Switches (except ICX8200-C08ZP and ICX7150-C08PT)	Power Outlet Connector: NBR 14136 Equipment Connector: C13 Length: 1.8m Rating: 250v/10A	Spare of IEC Power Cord, BR Plug

RUCKUS ACCESSORY GUIDE

ELECTRICAL



POWER CORDS







Outlet Connector	Equipment Connector	SKU	Compatible Products	Description	Kit Contents
HIGH TEMPERATURE POWER CORDS WITH C15 EQUIPMENT CONNECTOR					
		PCAU5-C15	ICX8200-C08ZP and ICX7150-C08PT	Power Outlet Connector: AS 3112 Equipment Connector: C15 Length: 1.83m Rating: 250v/10A	Power Cord High Temperature C15, Australia, 250V 10A, 1.83m
		PCC14C15	ICX8200-C08ZP and ICX7150-C08PT	Power Outlet Connector: C14 Equipment Connector: C15 Length: 1.83m	Power Cord High Temperature, C14 to C15, 125V 13A, 1.83m
		PCC14C15-SHORT	ICX8200-C08ZP and ICX7150-C08PT	Power Outlet Connector: C14 Equipment Connector: C15 Length: 0.25m	Power Cord High Temperature, C14 to C15, 125V 13A, 0.25m
		PCCHINA-C15	ICX8200-C08ZP and ICX7150-C08PT	Power Outlet Connector: IEC 60309 Equipment Connector: C15 Length: 1.83m Rating: 250v/10A	Power Cord High Temperature C15, China, 250V 10A, 1.83m
		PCEURO-C15	ICX8200-C08ZP and ICX7150-C08PT	Power Outlet Connector: CEE 7/7 Equipment Connector: C15 Length: 1.83m Rating: 250v/16A	Power Cord High Temperature C15, Europe, 250V 16A, 1.83m
		PCINDIA-C15	ICX8200-C08ZP and ICX7150-C08PT	Power Outlet Connector: BS 546 Equipment Connector: C15 Length: 1.83m Rating: 250v/10A	Power Cord High Temperature C15, India, 250V 10A, 1.83m
		PCITALY-C15	ICX8200-C08ZP and ICX7150-C08PT	Power Outlet Connector: CEI 23-16 Equipment Connector: C15 Length: 1.83m Rating: 250v/10A	Power Cord High Temperature C15, Italy, 250V 10A, 1.83m
		PCJAPAN-C15	ICX8200-C08ZP and ICX7150-C08PT	Power Outlet Connector: JIS 8303 Equipment Connector: C15 Length: 1.83m Rating: 125v/7A	Power Cord High Temperature C15, Japan, 125V 7A, 1.83m

RUCKUS ACCESSORY GUIDE

ELECTRICAL



POWER CORDS

Outlet Connector	Equipment Connector	SKU	Compatible Products	Description	Kit Contents
HIGH TEMPERATURE POWER CORDS WITH C15 EQUIPMENT CONNECTOR					
		PCSWISS-C15	ICX8200-C08ZP and ICX7150-C08PT	Power Outlet Connector: SEV 1011 Equipment Connector: C15 Length: 1.83m Rating: 250v/10A	Power Cord High Temperature C15, Swiss, 250V 10A, 1.83m
		PCUK-C15	ICX8200-C08ZP and ICX7150-C08PT	Power Outlet Connector: BS 1363 Equipment Connector: C15 Length: 2.5m Rating: 250v/13A	Power Cord, High Temperature C15, United Kingdom, 250V 13A, 2.5m
		PCUSA-C15	ICX8200-C08ZP and ICX7150-C08PT	Power Outlet Connector: NEMA 5-15 Equipment Connector: C15 Length: 1.83m Rating: 125v/13A	Power Cord High Temperature C15, USA, 125V 13A, 1.83m

ICX SERIAL MGNT CABLES

SKU	Compatible Products	Description	Kit Contents
CC-RJ45-DB9	All ICX switches with RJ-45 console ports (ICX 7150, ICX 7650, ICX 7850, ICX8200)	Serial Console cable RJ45-RJ45 with RJ-45-DB9 Adapter (for RJ-45 console port)	1 Cable 1 Adapter
CC-USBC-USBA	ICX switches with USB Type-C Mgmt port (ICX 7150, ICX 7650, ICX 7850, ICX 8100, ICX 8200)	USB 2.0 Cable, Type-C to Type-A, 1 meter (for USB Type-C console port on ICX 7150)	1 Cable
CC-MINIUSB-RJ45	ICX switches with mini-USB Mgmt port (ICX 7250, ICX 7450, ICX 7750)	Console cable, male mini-USB to male RJ-45 with RJ-45 to DB-9 converter	1 Cable 1 Adapter

ICX MOUNT KITS






SKU	Compatible Products	Description
XBR-R000295	ICX 7000 series 24/48 port 1RU models ICX8100 ICX8200	Universal Rack Mount Kit, 4 post, for ICX 7000 series 24/48 port models
ICX-RMK-4POST-TL	ICX 7550 ICX 7850	ICX Tool-less 4-Post Rack Mount Kit
ICX7000-RMK	ICX 7000 series 24/48 port 1RU models ICX8100 ICX8200	Rack Mount Kit, 2-post for ICX 7000 series 24/48 port models
ICX6400-C12-MGNT	ICX 7150/6450/6430 12 Port Compact Switches	Magnetic Mount Kit for Ruckus ICX 12 port compact switches
ICX7000-C12-WMK	ICX7150-C12P & ICX7150-C08P & ICX7150-C10ZP & ICX8200-C08PT & ICX8200-C08ZP compact switches ICX8100-C08PF and ICX8100-C16PF	Compact Switch Wall Mount & Under Desk Mount Kit for ICX7150-C12P & ICX7150-C08P ICX7150-C08PT & ICX7150-C10ZP Compact Switch Wall Mount & Under Desk Mount Kit
ICX7000-C12-RMK	ICX7150-C12P & ICX7150-C08P & ICX7150-C08PT ICX8100-C08PF & ICX8100-C16PF ICX8200-C08PT & ICX8200-C08ZP compact switches	Compact Switch Rack Mount Kit for ICX7150-C12P & ICX7150-C08P
ICX7000-C10ZP-RMK	ICX7150-C10ZP compact switches	Compact Switch Rack Mount Kit for ICX7150-C10ZP
ICX-ADP-PLT	All ICX Compact switches	ICX Compact Switch Adapter Plate for wall mounting the ICX7150-C08PT and DIN mounting all other ICX compact switch models.
ICX-DIN-MNT	All ICX Compact switches	ICX Compact Switch DIN Rail Mount Kit. Note: Additional adapter plate required (ICX-ADP-PLT) to attach the Din Rail Mount Kit to all ICX compact switches except for the ICX7150-C08PT extended temperature switch.
RMK-LRM-ADP	All ICX switches	Rack Mount Kit for LRM adapters. This 1RU shelf can accommodate up to 8 LRM adapters.

RUCKUS ACCESSORY GUIDE

FIBER ACCESSORIES



FIBER

	SKU	Compatible Products	Description
	P01-0600-0000	H550, H350	Fiber Optic Enclosure Gen4, Fiber-to-Ethernet Media Converter. Field Installable Accessory for H550, H350.
	P01-0500-0000	H510	Fiber Optic Enclosure, Fiber-to-Ethernet Media Converter. Field Installable Accessory for H510
	P01-0300-0000	T300/301 series T310c/d P300	Weathertight Fiber Optic Enclosure, Field Installable Accessory for T300/T301 series and P300
	902-0501-0000	902-0500-0000 (Fiber Backpack)	Installation kit with Backpack cover and installation wall bracket for Standalone Backpack use-case
	902-0502-0000	902-0500-0000 (Fiber Backpack)	Cable cover to be installed on Backpack when 902-I100-XXXX (Ruckus IoT module with cover) is installed on H510

For Optics Accessories—please refer to the [RUCKUS Optics Family Data Sheet](#)

ruckusnetworks.com

Visit our website or contact your local RUCKUS representative for more information.

© 2025 CommScope, LLC. All rights reserved.

CommScope and the CommScope logo are registered trademarks of CommScope and/or its affiliates in the U.S. and other countries. For additional trademark information, see <https://www.commscope.com/trademarks>. All product names, trademarks and registered trademarks are property of their respective owners.

CO-113939.18-EN (09/25)

[Back to TOC page](#)