

Pictured: CEXT44S2XPQ1QG012F

Sub-unitized Fiber Trunks

CEX Sub-unitized Fiber Trunks are our top of the line product set. Ranging from 08F up to 144F using the latest 2.0mm Sub-unit diameter, it does not only provide high density with the smallest possible diameter, but also flexibility to double stagger and line up to your rack and panel layout.

Plenum-rated (OFNP/OFCP)


- 250micron; 2.0mm¹ Sub-units: 8 Fiber or 12 Fiber
- LC Uniboosts of Field-Reversible Polarity
- MTP® PROs of Field-Reversible Polarity

TIA-598-C Industry Color Coding Standards

- Yellow (OS2)
- Aqua (OM4 | OM3)
- Colored Breakouts Every 8 or 12 Fibers



note that 'LENGTH (RANGES)' refers to overall length as measured from connector tips, excluding industry standard tolerances

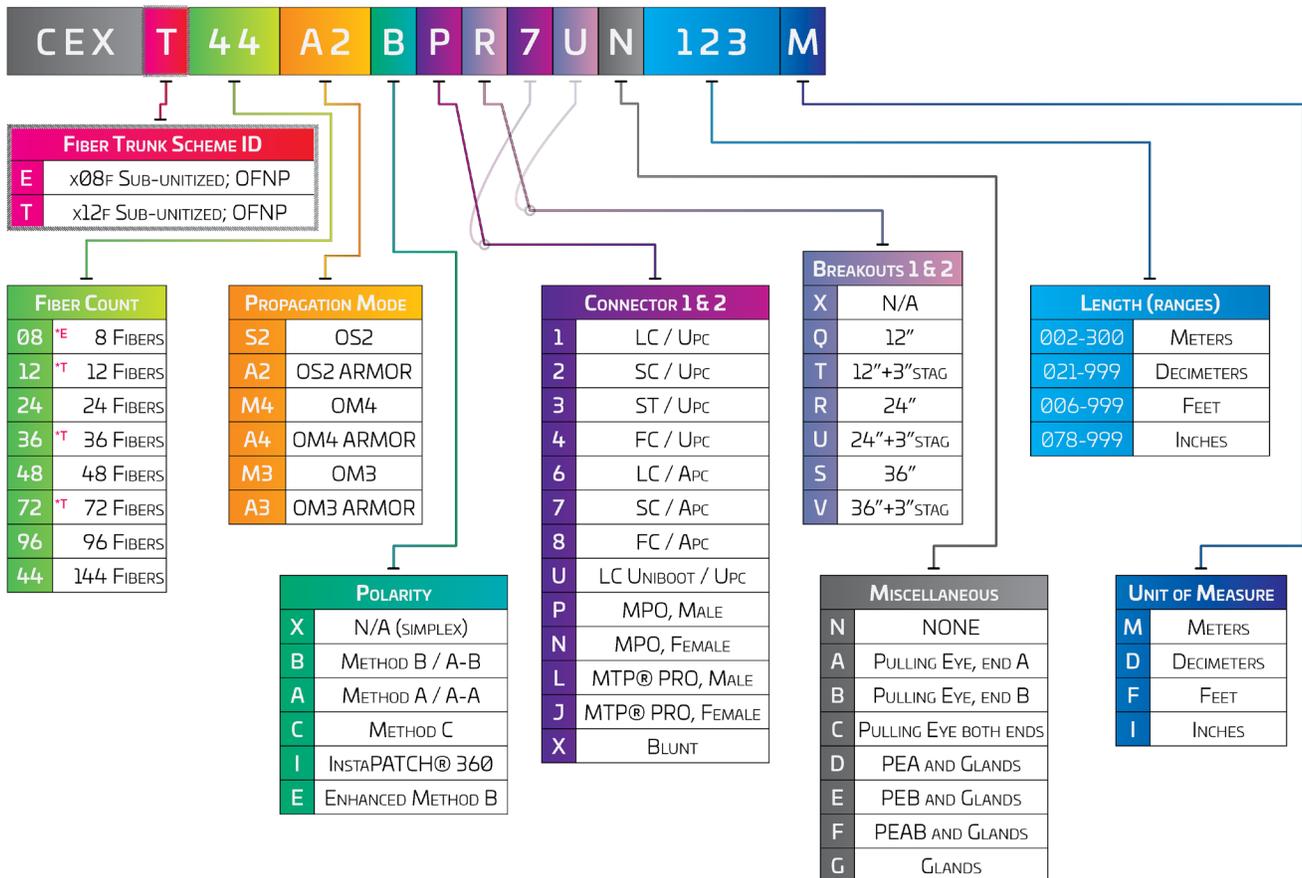

i. subject to availability -- 3.0mm diameter may be used in lieu of 2.0mm sub-units